


## SERIES 53



**STANDARD RUBBER WHEELS  
PRESSED STEEL DISCS CENTRE  
SWIVEL TOP PLATE BRACKET TYPE "SL"**

### Wheel description

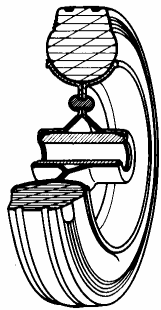


**Tread:** Standard rubber tread; hardness 85 +/-3 Shore A.

**Centre:** made of two riveted galvanized pressed steel discs.

**Hub:** the hub is available with plain bore and with roller bearings.

### Bracket description

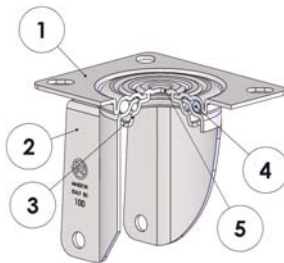

**Standard duty bracket type SL (max. carrying capacity 130 daN)**

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate