


SERIE 82



PNEUMATIC WHEELS RIB PROFILE POLYPROPYLENE CENTRE FIXED BRACKET TYPE "NL"

Wheel description

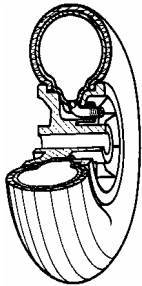


Tread: Pneumatic tyred wheels with rib profile and 4 plies; working pressure: 2 bar.

Centre: polypropylene.

Hub: the hub is available with plain bearing and with roller bearing.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

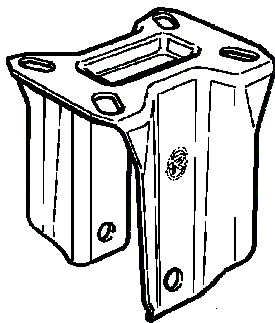

The bracket is made by an electrolytically galvanised steel fork.