


SERIES 82



**PNEUMATIC WHEELS RIB PROFILE
POLYPROPYLENE CENTRE
SWIVEL TOP PLATE BRACKET TYPE "NL"**


Wheel description

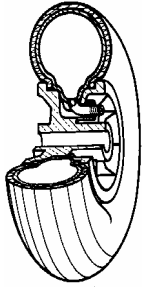

- Tread:** Pneumatic tyred wheels with rib profile and 4 plies; working pressure: 2 bar.
Centre: polypropylene.
Hub: the hub is available with plain bearing and with roller bearing.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

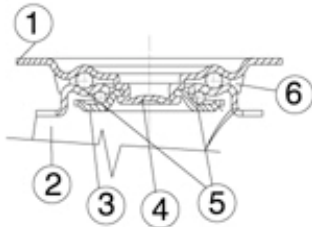

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** orange polyethylene
- Finishing:** electrolytic galvanisation
Fitting: top plate