

SERIES 60



INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, SWIVEL TOP PLATE BRACKET TYPE “NLX”

Wheel description




Tread: injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing, with stainless steel roller bearings and with stainless steel ball bearings.

Bracket description

Standard duty bracket type NLX (max. carrying capacity 400 daN)

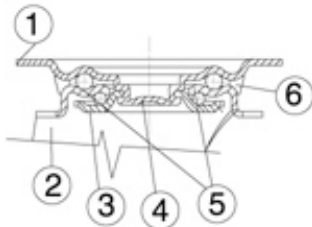

- 1) **Plate:** AISI 304 stainless steel
 - 2) **Fork:** AISI 304 stainless steel
 - 3) **Ball Racing Ring:** AISI 304 stainless steel
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** orange polyethylene
- Fitting:** top plate