

## SERIES 61



### INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, FIXED BRACKET TYPE “NLX”

#### Wheel description




**Tread:** injection polyurethane tread, hardness 80 Shore A; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

**Centre:** polyamide 6.

**Hub:** the hub is available with plain bearing, with stainless steel roller bearing, and with double shielding stainless steel ball bearing, coprinted in the centre of the wheel.

#### Bracket description

**Standard duty bracket type NLX (max. carrying capacity 400 daN)**

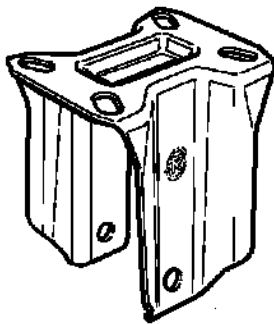

The bracket is made by AISI 304 stainless steel fork.

[www.tellurerota.com](http://www.tellurerota.com) – [www.laruotagiusta.it](http://www.laruotagiusta.it) – [www.therightwheel.com](http://www.therightwheel.com)