

SERIES 61



INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, SWIVEL TOP PLATE BRACKET TYPE “NLX”

Wheel description




Tread: injection polyurethane tread, hardness 80 Shore A; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing, with stainless steel roller bearing and with double shielding stainless steel ball bearing, coprinted in the centre of the wheel.

Bracket description

Standard duty bracket type NLX (max. carrying capacity 400 daN)

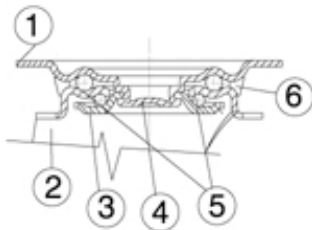

- 1) **Plate:** AISI 304 stainless steel
 - 2) **Fork:** AISI 304 stainless steel
 - 3) **Ball Racing Ring:** AISI 304 stainless steel
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** orange polyethylene
- Fitting:** top plate