


Straight stud standpipe adapters

Thread:
NPT (ANSI/ASME B 1
-20.01/01/1983)

Tube socket pre-assembled

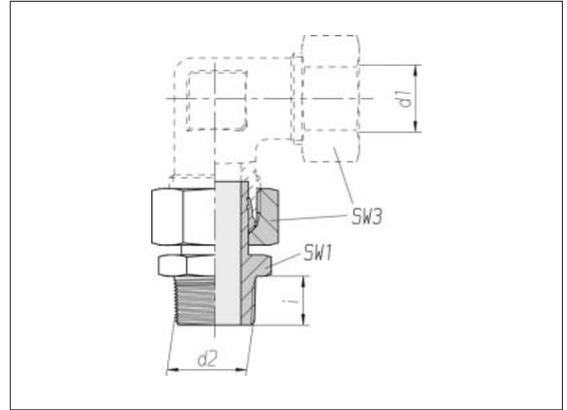

Series	Pressure	d2	SW1	SW3	l3 approx.	l5 approx.	i	Nm -10 %	kg/100 approx.	Order No.
L 6	PN 315	1/8 NPT	11	14	38.5	26.5	9.9	15	2.2	0 1 72 80 20 07*
L 8	PN 315	1/4 NPT	14	17	43.5	29.5	15.1	35	3.5	0 1 72 81 20 07
L 10	PN 315	1/4 NPT	14	19	45.5	30.5	15.1	35	4.2	0 1 72 82 20 07
L 12	PN 315	3/8 NPT	19	22	50	33	15.2	55	7.2	0 1 72 83 20 07
L 15	PN 315	1/2 NPT	22	27	56.5	35.5	19.8	110	11.0	0 1 72 84 20 07
L 18	PN 315	1/2 NPT	22	32	58.5	35	19.8	110	13.0	0 1 72 85 20 07
L 22	PN 160	3/4 NPT	27	36	63.5	36	20.1	175	18.2	0 1 72 86 20 07
L 28	PN 160	1 NPT	36	41	71	40.5	25	265	25.9	0 1 72 87 20 07
L 35	PN 160	1 1/4 NPT	46	50	83	48.5	25.6	315	42.8	0 1 72 88 20 07
L 42	PN 160	1 1/2 NPT	50	60	92.5	52.5	26	385	57.5	0 1 72 89 20 07
S 6	PN 630	1/4 NPT	14	17	46	30	15.1	35	4.3	0 1 72 90 20 07
S 8	PN 630	1/4 NPT	14	19	49.9	32.5	15.1	35	4.9	0 1 72 91 20 07
S 10	PN 630	3/8 NPT	19	22	52	34.5	15.2	55	8.0	0 1 72 92 20 07
S 12	PN 630	3/8 NPT	19	24	58	36.5	15.2	55	8.6	0 1 72 93 20 07
S 14	PN 630	1/2 NPT	22	27	62	40	19.8	110	13.8	0 1 72 94 20 07
S 16	PN 400	1/2 NPT	22	30	65	40.5	19.8	110	14.7	0 1 72 95 20 07
S 20	PN 400	3/4 NPT	27	36	73	46.5	20.1	175	23.9	0 1 72 96 20 07
S 25	PN 400	1 NPT	36	46	83.5	53.5	25	265	46.0	0 1 72 97 20 07
S 30	PN 400	1 1/4 NPT	46	50	92.5	57	25.6	315	65.2	0 1 72 98 20 07
S 38	PN 315	1 1/2 NPT	50	60	107	66	26	385	86.3	0 1 72 99 20 07

* Sample product code, see:
EVGE06L1/8NPT