


## PF 11

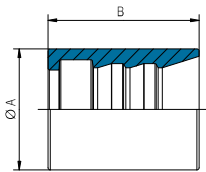


### Ghiera per tubo SAE 100 R1A/R1AT EN 853 1ST / 1SN EN 857 1SC / 2SC

Swaged ferrule for SAE 100/R1A/R1AT EN 853 1ST / 1SN EN 857 1SC / 2SC hose

Pressfassung für SAE 100/R1A/R1AT EN 853 1ST / 1SN EN 857 1SC / 2SC Schlauch

<b>CODICE</b> Part n° Bestell-Nr.	<b>DN Tubo</b> DN Hose DN Schlauch	<b>Ø A</b>	<b>B</b>
S 30 00 220 000 005	<b>3/16"</b> 5	17	26
S 30 00 220 000 006	<b>1/4"</b> 6	20	31
S 30 00 220 000 008	<b>5/16"</b> 8	21	31
S 30 00 220 000 010	<b>3/8"</b> 10	24	31
S 30 00 220 000 013	<b>1/2"</b> 12	28	35
S 30 00 220 000 016	<b>5/8"</b> 16	31	36
S 30 00 220 000 019	<b>3/4"</b> 19	35	42,5
S 30 00 220 000 025	<b>1"</b> 25	42	50,5
S 30 00 220 000 032	<b>1 1/4"</b> 31	52	59
S 30 00 220 000 038	<b>1 1/2"</b> 38	58	63
S 30 00 220 000 050	<b>2"</b> 51	71	70

## PF 12

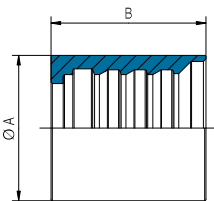


### Ghiera per tubo SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12

Swaged ferrule for SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12 hose

Pressfassung für SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12 Schlauch

<b>CODICE</b> Part n° Bestell-Nr.	<b>DN Tubo</b> DN Hose DN Schlauch	<b>Ø A</b>	<b>B</b>
S 30 00 340 000 005	<b>3/16"</b> 5	21	26
S 30 00 340 000 006	<b>1/4"</b> 6	22	30
S 30 00 340 000 008	<b>5/16"</b> 8	23	30
S 30 00 340 000 010	<b>3/8"</b> 10	26	31
S 30 00 340 000 013	<b>1/2"</b> 12	30	32
S 30 00 340 000 032	<b>1 1/4"</b> 31	57	58
S 30 00 340 000 038	<b>1 1/2"</b> 38	65	62
S 30 00 340 000 050	<b>2"</b> 51	79	73,5

## PF 13

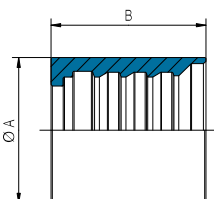

### Ghiera per tubo SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12

Swaged ferrule for SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12 hose

Pressfassung für SAE 100 R2A / R2AT EN 853 2ST / 2SN EN 856 4SP / R12 Schlauch

<b>CODICE</b> Part n° Bestell-Nr.	<b>DN Tubo</b> DN Hose DN Schlauch	<b>Ø A</b>	<b>B</b>
S 30 00 345 000 016	<b>5/8"</b> 16	33	38
S 30 00 345 000 019	<b>3/4"</b> 19	38	42,5
S 30 00 345 000 025	<b>1"</b> 25	46	51