


Struts

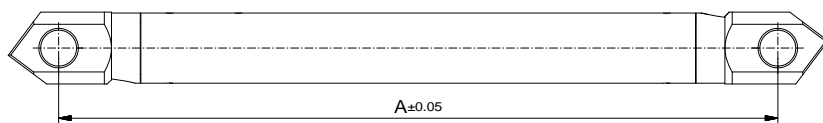

AF25 CLASSIC

Strut, 25x25

Grid 25, hole diameter 12,5mm

Nr.	A	B	g
81443	125	25	168
81444	250	25	285
81445	375	25	402
81327	500	25	518
81328	625	25	641
81329	750	25	752
81330	875	25	872
81331	1000	25	979

AF40 CLASSIC

Strut, 40x40

Grid 40, hole diameter 20mm

Nr.	A	B	g
81446	200	40	700
81447	400	40	1.226
81448	600	40	1.400
81407	800	40	2.258
81408	1000	40	2.240
81409	1200	40	3.161
81410	1400	40	3.470
81411	1600	40	4.170

AF50 CLASSIC

Strut, 50x50


Grid 50, hole diameter 25mm

Nr.	A	B	g
82403	250	50	1.424
82404	500	50	2.534
82405	750	50	3.637
82406	1000	50	5.696
82407	1250	50	7.120
82408	1500	50	8.544
82409	1750	50	9.968
82410	2000	50	11.392

Profile angle brackets


Nr.	A (AF)	B	C	D	g
120511	25	81,5	6	24	194
120514	25	121,5	6	24	319
120512	40	81,5	10	39	315
120515	40	121,5	10	39	518
120513	50	81,5	12	49	396
120516	50	122,5	12	49	651

Profile angle brackets are also available in special lengths of up to 3000mm

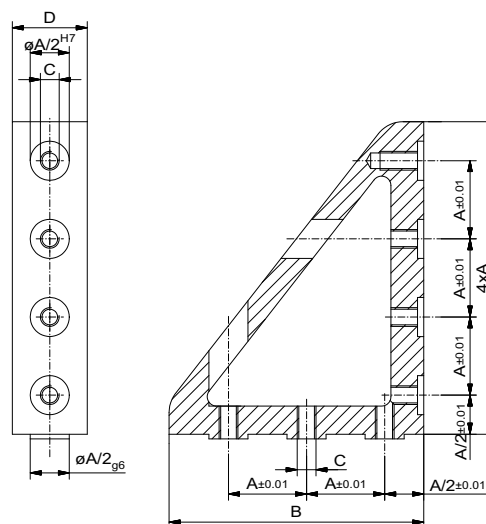

Profile angle brackets are also available on request in special widths

 Preference item:
Articles with green diamond →
are available ex stock!



→ Article colour anodized natural

→ Article colour anodized black