

AF25 CLASSIC

One row bar 25x25

Grid (A) 25, hole diameter 12,5mm

Nr.	B	g
21372	25	25
21373	50	51
21374	75	76
21375	100	102
21376	125	127
22961	150	152
22963	200	204
22882	250	255
21377	500	510

AF40 CLASSIC

One row bar 40x40

Grid (A) 40, hole diameter 20mm

Nr.	B	g
21273	40	104
21274	80	208
21279	120	404
21275	160	419
21276	200	523
20813	240	628
20815	320	1.098
20814	400	1.046
21304	800	2.947

AF50 CLASSIC

One row bar 50x50

Grid (A) 50, hole diameter 25mm

Nr.	B	g
28177	50	335
28178	100	408
28179	150	613
28180	200	900
28181	250	1.023
28182	300	960
28183	400	1.280
28184	500	2.047
28185	1000	3.200


AF25 CLASSIC

Two row bar 50x50

Grid (A) 25, hole diameter 12,5mm

Nr.	B	g
21378	50	204
21379	75	308
21380	100	410
21381	125	510
22965	150	610
22967	200	819
22883	250	1.025
21382	500	2.020
22634	1000	4.030

AF40 CLASSIC

Two row bar 80x80

Grid (A) 40, hole diameter 20mm


Nr.	B	g
21298	80	840
21299	120	1.257
21300	160	1.682
21301	200	2.080
20817	240	2.511
20818	280	2.900
20434	320	3.357
20435	400	4.150
21302	800	8.411

AF50 CLASSIC

Two row bar 100x100

Grid (A) 50, hole diameter 25mm

Nr.	B	g
28186	100	1.637
28187	150	2.490
28188	200	6.460
28189	250	4.095
28190	300	4.915
28191	400	6.555
28192	500	4.960
28193	1000	9.750

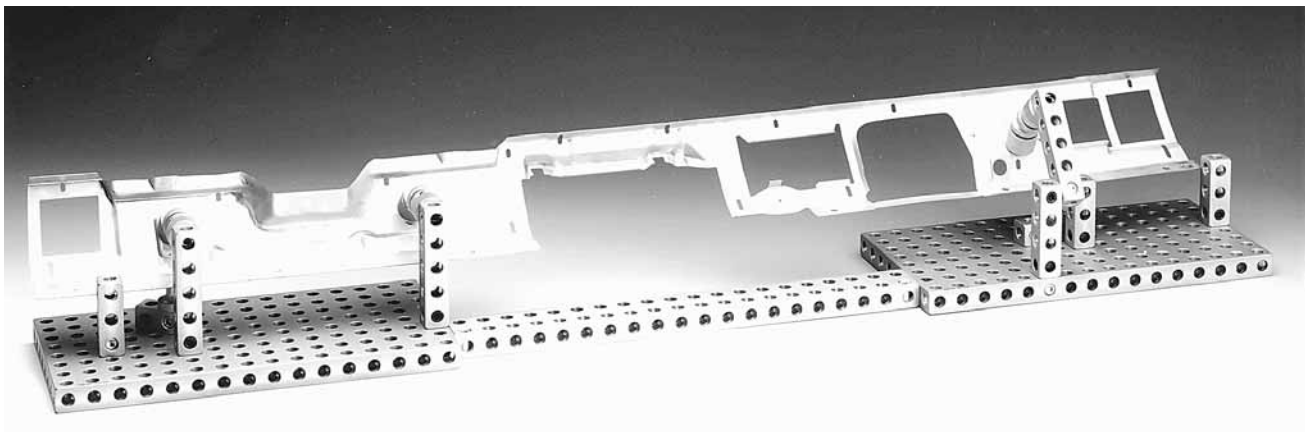

ALUFIX CLASSIC bars can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request

Other dimensions on request