


Struts

Alufix ECO

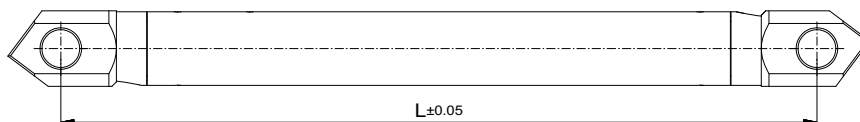

AF25 ECO

Struts, 25x25

Grid 25, grid hole dia 12,5mm

Nr.	L	g
81443-E	125	168
81444-E	250	285
81445-E	375	402
81327-E	500	518
81328-E	625	641
81329-E	750	752
81330-E	875	872
81331-E	1000	979

AF40 ECO

Struts, 40x40

Grid 40, grid hole dia 20mm


Nr.	L	g
81446-E	200	700
81447-E	400	1.226
81448-E	600	1.400
81407-E	800	2.258
81408-E	1000	2.240
81409-E	1200	3.161
81410-E	1400	3.665
81411-E	1600	4.110

AF50 ECO

Struts, 50x50

Grid 50, grid hole dia 25mm

Nr.	L	g
82403-E	250	1.424
82404-E	500	2.534
82405-E	750	3.637
82406-E	1000	5.696
82407-E	1250	7.120
82408-E	1500	8.544
82409-E	1750	9.968
82410-E	2000	11.392

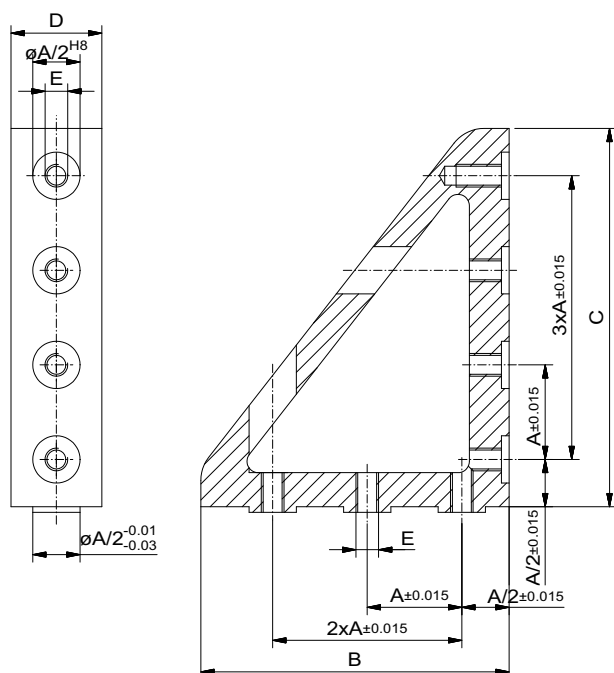

Profile angle brackets

Nr.	A(AF)	E	D x B x C	g
120511-E	25	6	24x81,5x100	194
120514-E	25	6	24x121,5x150	319
120512-E	40	10	39x81,5x100	315
120515-E	40	10	39x121,5x151	518
120513-E	50	12	49x81,5x100	396
120516-E	50	12	49x122,5x150	651



i Profile angle brackets are also available in special lengths of up to 3000mm. Special connection elements are required to assemble angle brackets, they are shown on page 152